


INCH

Steel PART #	Stainless Steel PART #	Thread	Thread Lgth	d ₂	d ₃	h	k
KK-2531	KK-2531SS	1/4-20	5/16	1	1/2	5/8	1/4
KK-2537	KK-2537SS	1/4-20	3/8	1	1/2	5/8	1/4
KK-2550	KK-2550SS	1/4-20	1/2	1	1/2	5/8	1/4
KK-2562	KK-2562SS	1/4-20	5/8	1	1/2	5/8	1/4
KK-2575	KK-2575SS	1/4-20	3/4	1	1/2	5/8	1/4
KK-2510	KK-2510SS	1/4-20	1	1	1/2	5/8	1/4
KK-2512	KK-2512SS	1/4-20	1-1/4	1	1/2	5/8	1/4
KK-3150	KK-3150SS	5/16-18	1/2	1-1/4	5/8	3/4	1/4
KK-3162	KK-3162SS	5/16-18	5/8	1-1/4	5/8	3/4	1/4
KK-3175	KK-3175SS	5/16-18	3/4	1-1/4	5/8	3/4	1/4
KK-3110	KK-3110SS	5/16-18	1	1-1/4	5/8	3/4	1/4
KK-3112	KK-3112SS	5/16-18	1-1/4	1-1/4	5/8	3/4	1/4
KK-3115	KK-3115SS	5/16-18	1-1/2	1-1/4	5/8	3/4	1/4
KK-3762	KK-3762SS	3/8-16	5/8	1-3/8	3/4	1	5/16
KK-3775	KK-3775SS	3/8-16	3/4	1-3/8	3/4	1	5/16
KK-3710	KK-3710SS	3/8-16	1	1-3/8	3/4	1	5/16
KK-3712	KK-3712SS	3/8-16	1-1/4	1-3/8	3/4	1	5/16
KK-3715	KK-3715SS	3/8-16	1-1/2	1-3/8	3/4	1	5/16
KK-5010	KK-5010SS	1/2-13	1	1-3/8	7/8	1	5/16
KK-5015	KK-5015SS	1/2-13	1-1/2	1-3/8	7/8	1	5/16
KK-5020	KK-5020SS	1/2-13	2	1-3/8	7/8	1	5/16

METRIC

Steel PART #	Stainless Steel PART #	Thread	Thread Lgth	d ₂	d ₃	h	k
361203006	361203006SS	M3 x .5	6mm	12mm	6mm	7.5mm	2.5mm
361203010	361203010SS	M3 x .5	10	12	6	7.5	2.5
361203012	361203012SS	M3 x .5	12	12	6	7.5	2.5
361203016	361203016SS	M3 x .5	16	12	6	7.5	2.5
-	361203506SS	M3.5 x .6	6	12	6	7.5	2.5
-	361203508SS	M3.5 x .6	8	12	6	7.5	2.5
-	361203510SS	M3.5 x .6	10	12	6	7.5	2.5
-	361203512SS	M3.5 x .6	12	12	6	7.5	2.5
-	361203516SS	M3.5 x .6	16	12	6	7.5	2.5
361604005	361604005SS	M4 x .7	5	16	8	9.5	3.5
361604008	361604008SS	M4 x .7	8	16	8	9.5	3.5
361604010	361604010SS	M4 x .7	10	16	8	9.5	3.5
361604012	361604012SS	M4 x .7	12	16	8	9.5	3.5
361604016	361604016SS	M4 x .7	16	16	8	9.5	3.5
361604020	361604020SS	M4 x .7	20	16	8	9.5	3.5
361604025	361604025SS	M4 x .7	25	16	8	9.5	3.5
362005006	362005006SS	M5 x .8	6	20	10	11.5	4
362005008	362005008SS	M5 x .8	8	20	10	11.5	4
362005010	362005010SS	M5 x .8	10	20	10	11.5	4
362005012	362005012SS	M5 x .8	12	20	10	11.5	4
362005016	362005016SS	M5 x .8	16	20	10	11.5	4
362005020	362005020SS	M5 x .8	20	20	10	11.5	4
362406008	362406008SS	M6 x 1.0	8	24	12	15	5
362406010	362406010SS	M6 x 1.0	10	24	12	15	5
362406012	362406012SS	M6 x 1.0	12	24	12	15	5
362406016	362406016SS	M6 x 1.0	16	24	12	15	5
362406020	362406020SS	M6 x 1.0	20	24	12	15	5
362406025	362406025SS	M6 x 1.0	25	24	12	15	5
-	362406030SS	M6 x 1.0	30	24	12	15	5
363008012	363008012SS	M8 x 1.25	12	30	16	18	6
363008016	363008016SS	M8 x 1.25	16	30	16	18	6
363008020	363008020SS	M8 x 1.25	20	30	16	18	6
363008025	363008025SS	M8 x 1.25	25	30	16	18	6
363008030	363008030SS	M8 x 1.25	30	30	16	18	6
363008040	363008040SS	M8 x 1.25	40	30	16	18	6
363610016	363610016SS	M10 x 1.5	16	36	20	23	8
363610020	363610020SS	M10 x 1.5	20	36	20	23	8
363610025	363610025SS	M10 x 1.5	25	36	20	23	8
363610030	363610030SS	M10 x 1.5	30	36	20	23	8
363610040	363610040SS	M10 x 1.5	40	36	20	23	8
-	363612025SS	M12 x 1.75	25	36	20	23	8
-	363612030SS	M12 x 1.75	30	36	20	23	8
-	363612040SS	M12 x 1.75	40	36	20	23	8
-	363612050SS	M12 x 1.75	50	36	20	23	8

Knurled Thumb Screws

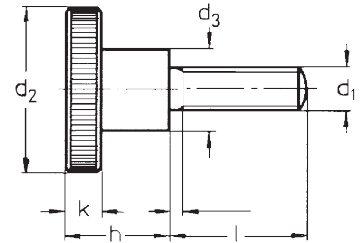

- ▶ Inch and metric sizes available
- ▶ Available in steel and stainless steel
- ▶ Solid one piece construction
- ▶ Straight knurl
- ▶ Metric sizes meet DIN464 standards